


Accessories RA

Adapter RA-40-UG20 UG25

Order number 50486391

Net weight 0.037 kg

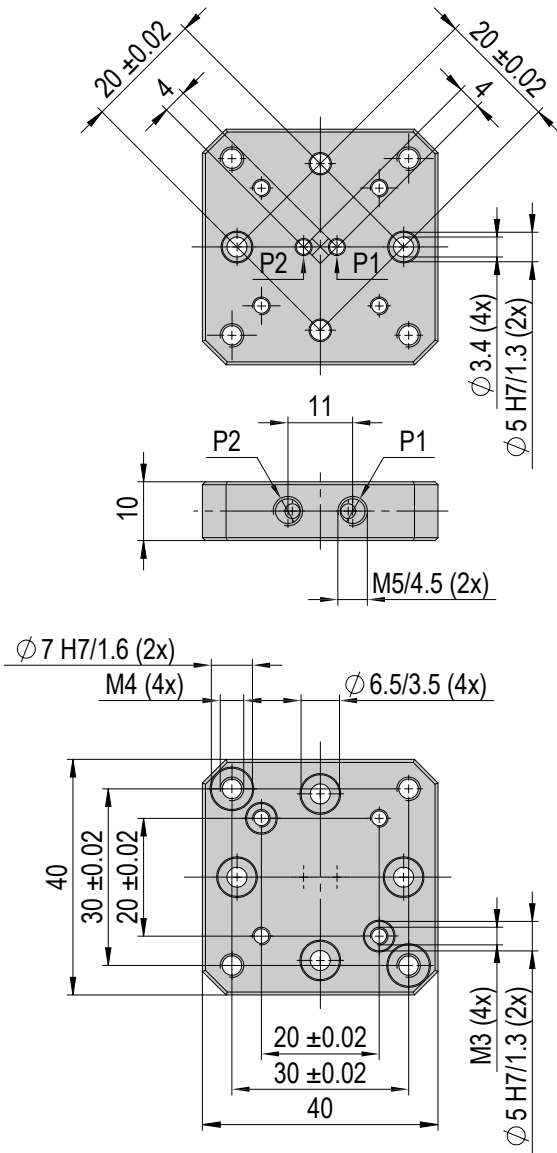

Included in the delivery


(Catalogue HT accessories)

- 2x Mounting screw M3x10
- 2x Centering bushing Ø5x2.5

Adapter RA-40-PG 12

Order number 50486392

Net weight 0.02 kg

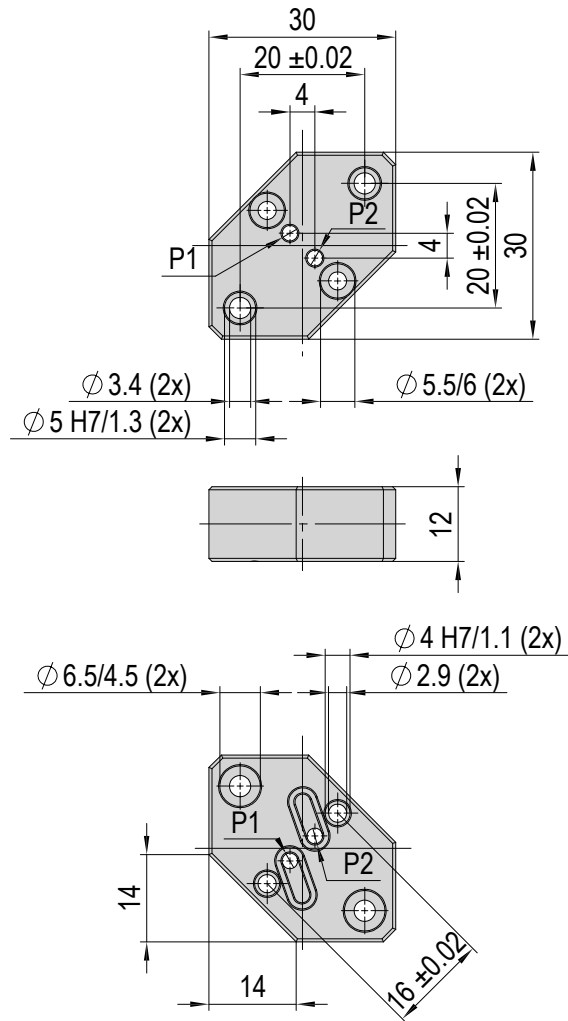

Included in the delivery

(Catalogue HT accessories)


- 2x Mounting screw M3x12
- 2x Centering bushing Ø5x2.5
- 2x O-ring 6x1 mm

Accessories RA

Adapter RA-40-PG 16

Order number 50486393

Net weight 0.022 kg

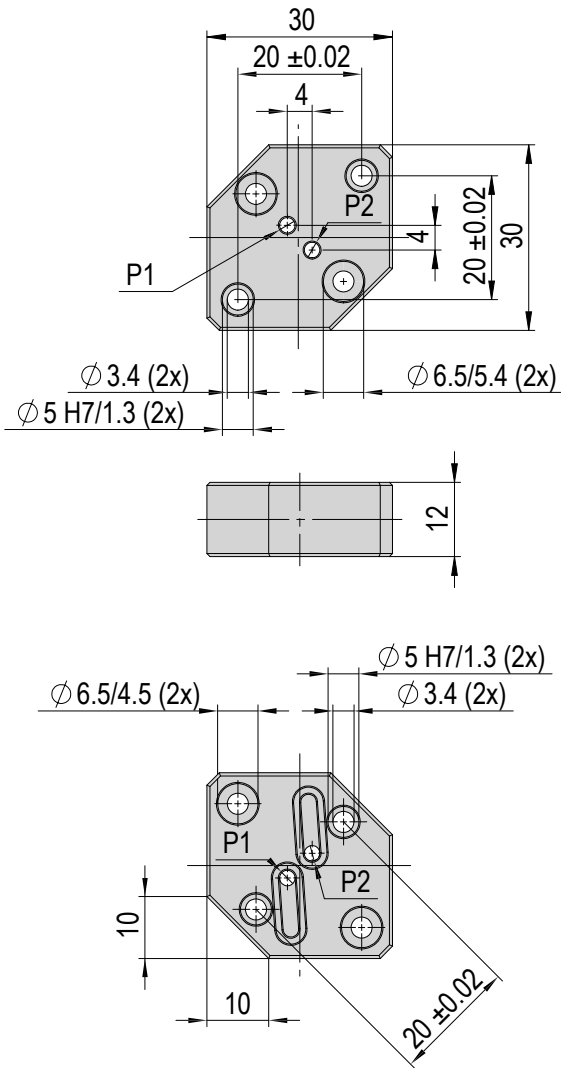

Included in the delivery


(Catalogue HT accessories)

- 2x Mounting screw M3x12
- 2x Centering bushing Ø5x2.5
- 2x O-ring 8x1 mm

Adapter RA-40-PG 20

Order number 50486394

Net weight 0.025 kg

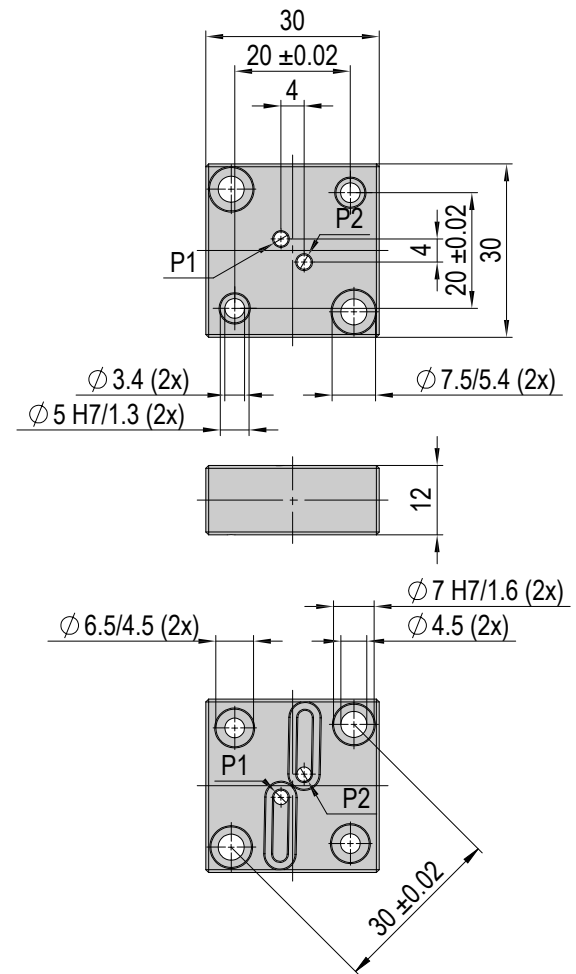


Included in the delivery

(Catalogue HT accessories)


- 2x Mounting screw M3x12
- 2x Centering bushing Ø5x2.5
- 2x O-ring 10x1 mm

Accessories RA

Proximity switch cable-R11-0-open	5m-0-open	10m-0-open
Order number	50488105	50488104
Net weight	0.24 kg	0.48 kg
Cable Ø	5.6 mm	5.6 mm
Min. bending radii	75 mm	75 mm
Material	PUR	PUR
A	5 m	10 m

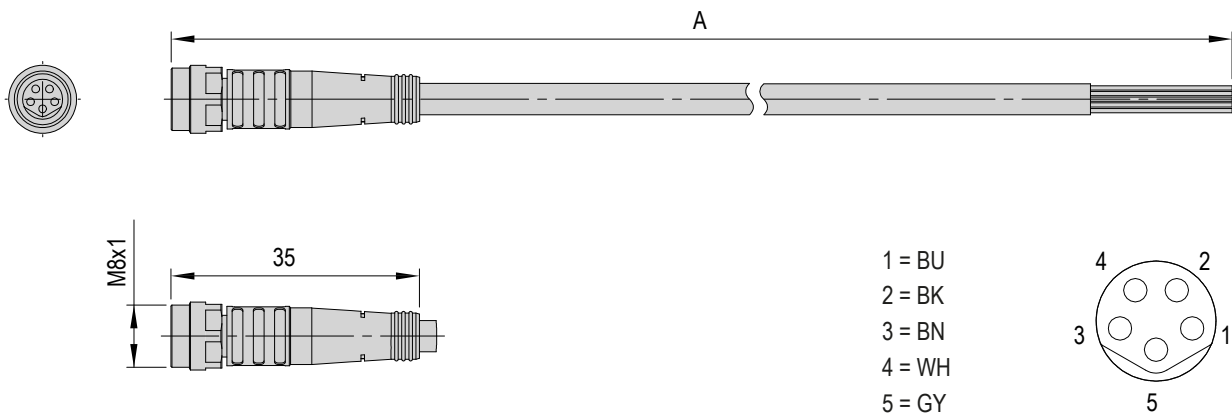


Proximity switch cable-R11-90-open	5m-0-open	10m-90-open
Order number	50488107	50488106
Net weight	0.24 kg	0.48 kg
Cable Ø	5.6 mm	5.6 mm
Min. bending radii	75 mm	75 mm
Material	PUR	PUR
A	5 m	10 m

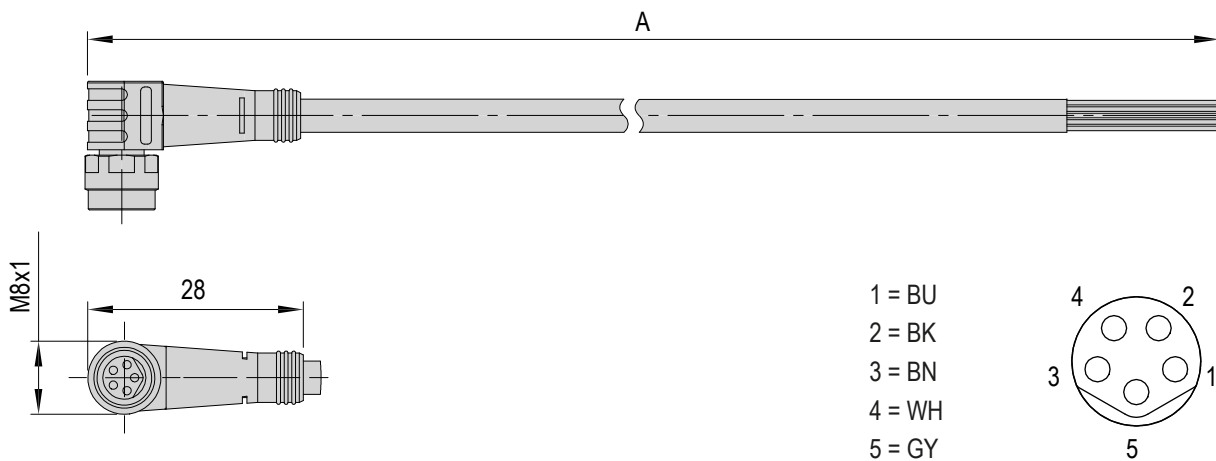


Accessories RA

Extension-R11-90-0-X	1m-90-0-X
Order number	50488108
Net weight	0.06 kg
Cable Ø	5.6 mm
Min. bending radii	75 mm
Material	PUR
A	1 m

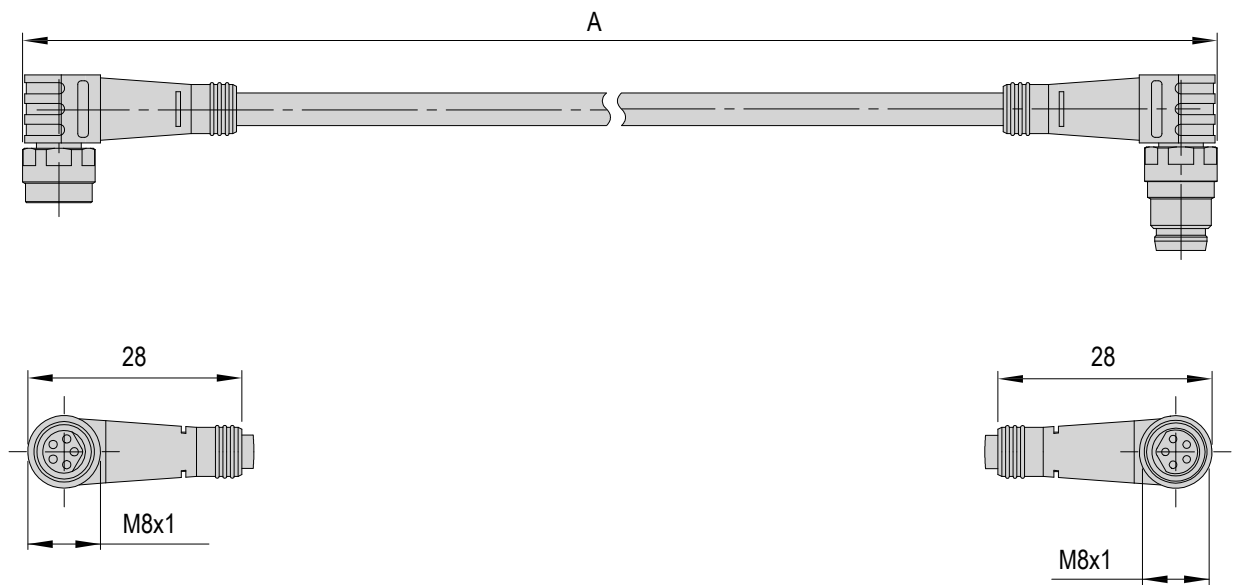


Extension-R11-0-90-X	1m-0-90-X
Order number	50488109
Net weight	0.06 kg
Cable Ø	5.6 mm
Min. bending radii	75 mm
Material	PUR
A	1 m

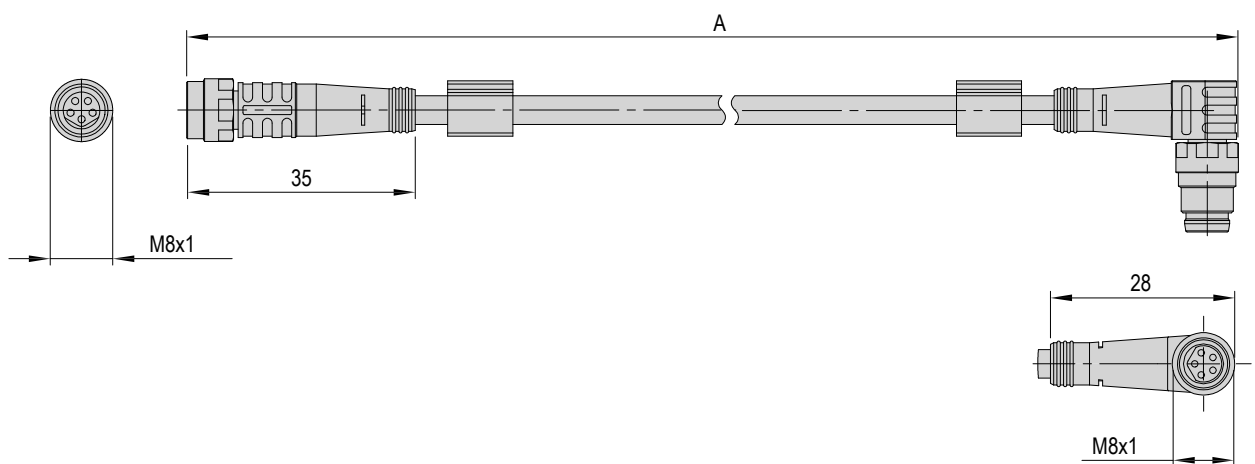


Accessories RA

Extension-R11-0-0-X	1m-0-0-X
Order number	50488110
Net weight	0.06 kg
Cable Ø	5.6 mm
Min. bending radii	75 mm
Material	PUR
A	1 m

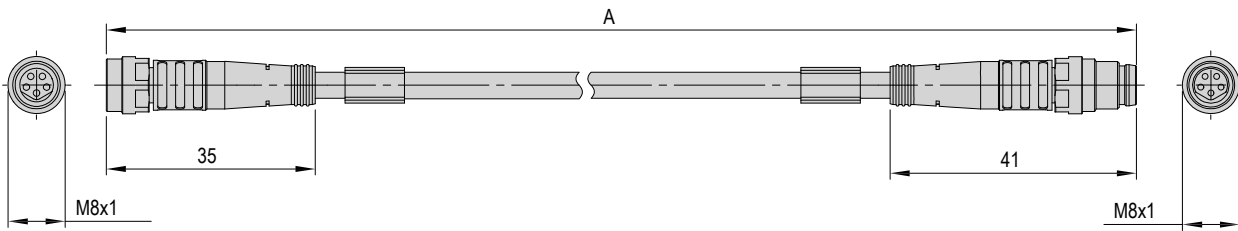

Extension-R11-90-0-X_1	1m-90-0-X
Order number	50488111
Net weight	0.06 kg
Cable Ø	5.6 mm
Min. bending radii	75 mm
Material	PUR
A	1 m

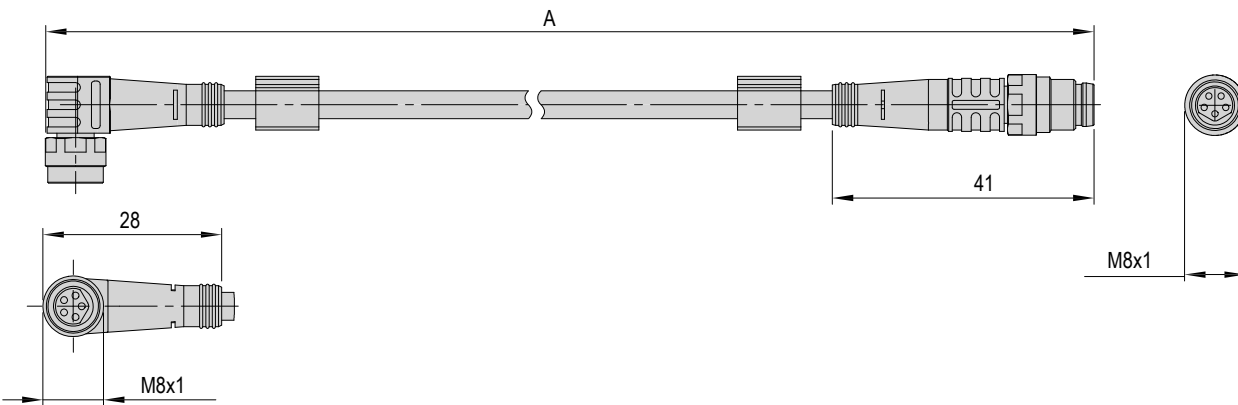

Accessories RA

Y-Distributor plug-R12

Order number	50488112
Net weight	0.01 kg

