

强制性认证产品符合性自我声明

自我声明编号: 2020980305003326



TopWorx Inc. (生产者) 及世格流体控制(上海)有限公司(生产者授权代表) 确认知晓《强制性产品认证自我声明实施规则》以及相关产品强制性认证实施规则的要求, 对本声明承担全部法律责任。

TopWorx Inc. (生产者) 及世格流体控制(上海)有限公司(生产者授权代表) 声明以下产品已按照《强制性产品认证自我声明实施规则》以及相关产品强制性认证实施规则的要求进行检测, 符合相关标准要求; 自本声明签署之日起, 生产和销售的产品持续符合以下标准与实施规则的要求; 保存本声明涉及的技术文档至少10年; 正确使用强制性产品认证标志; 如产品或其符合性信息发生变更, 将及时更新技术文档并报送产品变更信息。


生产者名称: TopWorx Inc.
生产者地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
依据的强制性产品认证规则: CNCA-00C-008: 2019 强制性产品认证实施规则自我声明
产品名称: 磁性开关
产品系列、型号、规格: (见附页)
依据的标准: GB/T 14048.5-2017
生产企业名称: TopWorx Inc.
生产企业地址: 3300 Fern Valley Road, Louisville, KY 40213, USA

生产者联系信息

名称: TopWorx Inc.
地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
联系人: Robert Coale
电话: +1 502 873 4629
电子邮箱: Robert.Coale@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: Louisville
指定签字人:
签章:

授权代表信息

名称: 世格流体控制(上海)有限公司
地址: 上海市市辖区松江区新桥镇新庙三路480号18幢号楼1楼、2楼和3楼B区
联系人: 刘钦海
电话: 18501785664
电子邮箱: QinHai.Liu@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: 上海市
指定签字人:
签章:

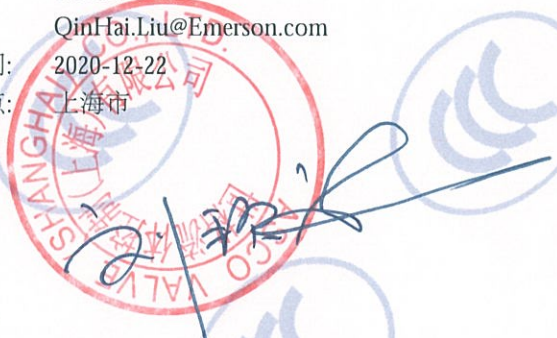

注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)




自我声明编号: 2020980305003326

产品系列、型号、规格:

11,12,21,22: Ui:480V;Uimp:4kV;Ith:10A;11,21:AC-12:Ue/Ie:AC240V/5A,AC120V/10A,AC480V/2.5A;DC-12:Ue/Ie:DC24V/3A;12,22:AC-12:Ue/Ie:AC30V/0.25A;DC-12:Ue/Ie:DC30V/0.25A;外壳防护等级:IP64; 型号解释见附件

生产者联系信息

名称: TopWorx Inc.
地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
联系人: Robert Coale
电话: +1 502 873 4629
电子邮箱: Robert.Coale@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: Louisville
指定签字人:
签章:

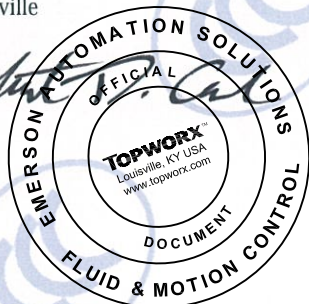

授权代表信息

名称: 世格流体控制(上海)有限公司
地址: 上海市市辖区松江区新桥镇新庙三路480号18幢号楼1楼、2楼和3楼B区
联系人: 刘钦海
电话: 18501785664
电子邮箱: QinHai.Liu@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: 上海市
指定签字人:
签章:



注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2020980305003326

产品系列、型号、规格(附件):


- Go Switch Models 11, 12, 21, 22
E.g. Model No: 11 - 1 1 5 2 8 - 00M P XXXX
① ② ③ ④ ⑤ ⑥ ⑦ ⑧ ⑨
- ① Model 型号
11: 1-1/2in square x 4-9/16in long. (Add 1/2in in length for bottom conduit outlet) (1-1/2in square x 4-9/16in 长, (底部导管出口长度加 1/2in))
12: Identical dimensions as stated above for Model 11. (与上述型号 11 相同的尺寸。)
21: 1-1/2in square x 3-3/16in long. (Add 1/2in in length for bottom conduit outlet) (1-1/2in square x 3-3/16in 长, (底部导管出口长度加 1/2in))
22: Identical dimensions as stated above for Model 21 (与上述型号 21 相同的尺寸)
- ② Contact Form 连接类型
1: SPDT (Form C)
3: SPDT (Form C), latching (maintained contact) (Conduit outlet position 2, 4, or 5 ONLY)
5: DMDB (Form Z), two circuit (Model 11, 12 ONLY)
6: DMDB (Form Z), latching (maintained contact) (Conduit outlet position 2, 4, or 5 ONLY) (Model 11, 12 ONLY)
- ③ Sensing Range 感应范围
1: Standard sensing - approx. 3/8in with ferrous target (标准传感 - 约3/8英寸含铁靶)
2: Extended sensing - approx. 9/16in with ferrous target (Contact Form 1 or 3 ONLY) (Model 11, 12 ONLY) (扩展传感 - 大约9/16英寸带有铁质目标 (仅限触点形式1或3) (仅适用于型号11,12))
7: Precision sensing - approx. 1/4in with ferrous target (精确传感 - 大约1/4英寸带有铁靶)
- ④ Conduit Outlet Position 出口位置
1: Behind, or opposite, of the sensing face (感应面的后面或相对的)
2: Left of the sensing face (传感面的左侧)
3: Right of the sensing face (传感面的右侧)
4: Same side as the sensing face (与传感面相同的一侧)
5: Bottom of switch enclosure (开关盒底部)
- ⑤ Enclosure Material 外壳材料
1: Brass, coated with flat black lacquer paint (Models 11, 21 ONLY) (黄铜, 涂有黑色漆面漆 (仅限11型, 21型))
2: Stainless steel (304 or 316L) (不锈钢 (304或316L))
3: Brass, coated with corrosion-resistant polyurethane (Models 11, 21 ONLY) (黄铜, 涂有耐腐蚀聚氨酯 (仅限11型, 21型))
4: Stainless steel (304 or 316L), coated with corrosion-resistant polyurethane (Models 11, 21 ONLY) (不锈钢 (304或316L), 涂有耐腐蚀聚氨酯 (仅限型号11,21))
- ⑥ Area Classification* 区域分类
0: CSA/FM Class I, Div2, GrABCD; Class II, Div1&2, GrEFG; Class III (Termination option 00, 00M) (Models 11, 21)
2: High Temperature rated to 350°F (176°C) (Model 11 ONLY) (Contact Form 1 or 3, Sensing 1, Enclosure Material 2 or 4 ONLY)
3: UL/cUL Class I, Div1, GrABCD; Class II, Div1, GrEFG; Class III (Enclosure Material 2 or 4, Termination A, B, or F ONLY) (Models 11, 21 ONLY)
(Lead seal required within 18in of enclosure)
4: CSA/FM Class I, Div1, GrABCD; Class II, Div1, GrEFG; Class III (Enclosure Material 2 or 4, Termination A, B, or F ONLY) (Models 11, 21 ONLY)
(Lead seal required within 18in of enclosure)

生产者联系信息

名称: TopWorx Inc.
地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
联系人: Robert Coale
电话: +1 502 873 4629
电子邮箱: Robert.Coale@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: Louisville
指定签字人:
签章:

授权代表信息

名称: 世格流体控制(上海)有限公司
地址: 上海市市辖区松江区新桥镇新庙三路480号18幢号楼1楼、2楼和3楼B区
联系人: 刘钦海
电话: 18501785664
电子邮箱: QinHai.Liu@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: 上海市
指定签字人:
签章:

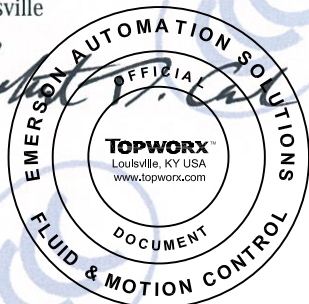

注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)




自我声明编号: 2020980305003326

产品系列、型号、规格(附件):

- 6: CSA/FM Class I, Div2, GrABCD; Class II, Div2, GrFG; Class III (Termination A, B, or F, Models 11, 21 ONLY)
- 7: UL listed Ordinary Locations for Canada (cUL) (Models 11, 21 ONLY)
- 8: UL listed Ordinary Locations for U.S. (UL) (Models 11, 21 ONLY)
- 9: ATEX/IECEx rated Ex db eb IIC T6 Gb; Ex tb IIIC T85°C Db; Tamb: -40°C to +60°C; IP66/68, or may be marked,
 - Ex d e IIC T6 Gb; Ex tb IIIC T85°C Db; Tamb: -40°C to +60°C; IP66/68 (Models 12, 22 ONLY) (Termination 00 or 00M)
- F: ATEX/IECEx rated Ex ia IIC T6 Ga; Ex ia IIIC T85°C Da; Tamb: -40°C to +50°C (Models 11, 21 ONLY) (Termination 00, 00M, A, B, F, S, DBA,
 - DBD, DBG, DCA, DCD, DCG)
- G: ATEX/IECEx rated Ex ia IIC T4 Ga; Ex ia IIIC T135°C Da; Tamb: -40°C to +100°C (Models 11, 21 ONLY) (Termination 00, 00M, A, B, F, S, DBA,
 - DBD, DBG, DCA, DCD, DCG)
- H: ATEX/IECEx rated Ex ia IIC T3 Ga; Ex ia IIIC T200°C Da; Tamb: -40°C to +150°C (Models 11, 21 ONLY) (Termination F and S)
- ⑦ Termination (Field Wiring) 接线/触点
 - Terminal Block 接线端子
 - 00: 1/2" - 14 NPT
 - 00M: M20
 - Lead Wires (18 gauge, PVC insulated) 引线 (18规格, PVC绝缘)
 - A2: 36"
 - A3: 72"
 - A4: 144"
 - A___ (Greater than 144" - specify length in 5ft increments) (大于144" - 指定长度, 以5英尺为增量)
 - Cable (16 gauge, SO rubber insulated) 电缆 (16规格, SO橡胶绝缘)
 - B2: 36"
 - B3: 72"
 - B4: 144"
 - B___ (Greater than 144" - specify length in 5ft increments) (大于144" - 指定长度, 以5英尺为增量)
 - Quick Disconnect Mini Connector (Approval must be 7 or 8; 3 pin is 8 only) 快速断开微型连接器 (区域必须为7或8; 3针仅为8)
 - DCA: 3 pin
 - DCD: 4 pin
 - DCG: 5 pin
 - SubSea Connector (Approval must be 7 or 8; Enclosure must be 2 or 4) SubSea连接器 (区域必须为7或8; 外壳必须为2或4)

生产者联系信息

名称: TopWorx Inc.
地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
联系人: Robert Coale
电话: +1 502 873 4629
电子邮箱: Robert.Coale@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: Louisville
指定签字人:
签章:

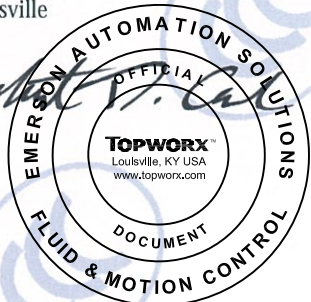

授权代表信息

名称: 世格流体控制(上海)有限公司
地址: 上海市市辖区松江区新桥镇新庙三路480号18幢号楼1楼、2楼和3楼B区
联系人: 刘钦海
电话: 18501785664
电子邮箱: QinHai.Liu@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: 上海市
指定签字人:
签章:



注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。

强制性认证产品符合性自我声明(附页)



自我声明编号: 2020980305003326

产品系列、型号、规格(附件):

3DD: 3 Pin
4DD: 4 Pin
3DE: 3 Pin 90°
4DE: 4 Pin 90°

- Hi-Temp Leads (18 gauge, Teflon™ insulated) 高温引线 (18规格, Teflon™绝缘)

F2: 36"

F3: 72"

F4: 144"

F___ (Greater than 144" - specify length in 5ft increments) (大于144" - 指定长度, 以5英尺为增量)

- Brad Harrison micro change type (1/4 in. - 18NPT), limited to 250 V, 4A. Brad Harrison微变型 (1/4英寸 - 18NPT), 限制为250 V, 4A.

DMD: 4 Pin

8. Regional Certificates 区域证书

Blank : No Regional Certificates

P : PESO certified Hazardous Locations (Area Class 9, F, G, H)

K : KOSHA certified Ex d (Area Classification 9 ONLY)

9. Custom Number 客户编码

May include 4 numbers indicating custom quote. Does not affect protection method. The 4 custom quote number is only for commercial use, does not affect product safety or production process. 可能包含4个数字, 表示自定义报价 不影响保护方法。4个自定义报价编号仅用于商业用途, 不影响产品安全或生产过程。

生产者联系信息

名称: TopWorx Inc.
地址: 3300 Fern Valley Road, Louisville, KY 40213, USA
联系人: Robert Coale
电话: +1 502 873 4629
电子邮箱: Robert.Coale@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: Louisville
指定签字人:
签章:



授权代表信息

名称: 世格流体控制(上海)有限公司
地址: 上海市市辖区松江区新桥镇新庙三路480号18幢号楼1楼、2楼和3楼B区
联系人: 刘钦海
电话: 18501785664
电子邮箱: QinHai.Liu@Emerson.com
自我声明时间: 2020-12-22
自我声明地点: 上海市
指定签字人:
签章:



注: 有关本声明信息真伪可登录全国认证认可信息公共服务平台 (cx.cnca.cn) 或扫描右上角二维码查询。