



中国国家强制性产品认证证书



证书编号: 2021322307004289

认证委托人名称: BIFFI ITALIA s.r.l
 认证委托人地址: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy
 生产者名称: BIFFI ITALIA s.r.l
 生产者地址: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy
 生产企业名称: BIFFI ITALIA s.r.l
 企业地址: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy

产品名称: 角行程电动执行机构
 系列、规格、型号: EPI2-a, EPI2-Eb 系列
 标准: GB 3836.1-2010、GB 3836.2-2010、GB 3836.3-2010、
 GB 12476.1-2013、GB 12476.5-2013

上述产品符合强制性产品认证实施规则 CNCA-C23-01:2019 的要求, 特发此证。

发证日期: 2021年11月4日 有效期至: 2026年11月3日

首次发证日期: 2021年11月4日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

本证书的相关信息可通过国家认监委网站 www.cnca.gov.cn 查询



批准:



上海仪器仪表自控系统检验测试所有限公司



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION



CERTIFICATE NO: 2021322307004289

APPLICANT: BIFFI ITALIA s.r.l

ADDRESS: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy

MANUFACTURER: BIFFI ITALIA s.r.l

ADDRESS: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy

FACTORY: BIFFI ITALIA s.r.l

ADDRESS: Strada Biffi, 165, 29017 - Fiorenzuola D'Arda, PC - Italy

PRODUCTNAME: Quarter-Turn Electric Actuator

SERIES,SPECIFICATION,MODEL: EPI2-a , EPI2-EbSeries

STANDARDS: GB 3836.1-2010、 GB 3836.2-2010、 GB 3836.3-2010、
GB 12476.1-2013、 GB 12476.5-2013

This is to certify that the above mentioned product(s)complies with the requirements of implementation rules for compulsory certification (REFNO. CNCA-C23-01:2019).

Valid from:November 4, 2021

Valid until: November 3, 2026

Date of original certification:November 4, 2021

The validity of this certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

This certificate is available through CNCA's website: www.cnca.gov.cn



APPROVAL:



 Guo AiHua



Shanghai Inspection and Testing Institute of Instruments and Automation Systems Co., Ltd.

<http://www.sitiias.com.cn>

Building 9,103 Cao Bao Road, Shanghai 200233,China

Tel: +86 21 64510844

s 0005278



中国国家强制性产品认证证书



证书编号：2021322307004289

附 件

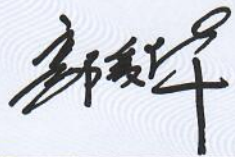
产品名称：角行程电动执行机构

型号规格：EPI2-*a*, EPI2-E*b*
*a*代表额定扭矩 (Nm)，代码可为 063、125、250、500、1000 或 2000。
*b*代表额定扭矩 (Nm)，代码可为6、13、25、51、91或171。

防爆标志：Ex d e IIB T5 Gb, Ex tD A21 IP66/68 T100°C

电气参数：

型号	EPI2-063、125	EPI2-250、500、1000、2000
	EPI2-E6、E13	EPI2-E25、E51、E91、E171
直流电压范围	24~48 Vdc、100~240 Vdc (±10%)	
单相电压范围	24~48 Vac、100~240 Vac (±10%) 50/60 Hz (±5%)	
三相电压范围	208~575 Vac (±10%) 50/60 Hz (±5%)	
最大电机标称功率	80W	300W
最大吸收功率	216W	480W
最大耗散功率	190W	380W

批 准： 



上海仪器仪表自控系统检验测试所有限公司