

ProLink® III Configuration and Service Software for Micro Motion and Rosemount Flow Meters

World class configuration, service, and troubleshooting tool

ProLink III delivers all the power and flexibility you need to configure and manage Micro Motion and Rosemount flow measurement devices and analyze process data. ProLink III provides an easy-to-use interface that allows you to have your flow meter up and running quickly no matter how complex your configuration or diagnostic needs are.

ProLink III provides an intuitive, dashboard-like interface where you can simultaneously access all the information you may need to assess your meter's health. You can easily see your process variables and alert conditions from a single screen to help when troubleshooting device behavior and can minimize expensive downtime.

ProLink III also provides configuration capabilities that allow you to save and upload configuration information from one device to another. Or, you can use the offline configuration tool to configure a device prior to making a physical connection. With features like these, you can more efficiently manage the set up and commissioning of your Micro Motion or Rosemount flow meters.

Streamline work practices

Identify process trends and remotely troubleshoot flow meters with ProLink III



Benefits:

- Task-oriented interface design that streamlines work practices
- Capability to diagnose meters remotely using Modbus/TCP connection
- Device simulation that allows you to understand your meter's capabilities and functionality
- Easily configures your transmitter from a single access point
- Simultaneously view process data from more than one meter
- Monitor system performance with trending and data logging
- Online process variable trending tool can highlight process control opportunities
- Easily view calibration and configuration data in a printable report that allows you to quickly reference a device's setup
- Offline configuration reduces connection time to meters in hazardous areas
- Guided connection tool with a drag-and-drop interface that allows you to easily configure your device connection
- Easy upgrade option available for ProLink II users

ProLink III Feature Comparison

| Features | Basic | Professional |
|------------------------------------|-------|--------------|
| Full configuration | ● | ● |
| Alert notification | ● | ● |
| Alert resolution guide | ● | ● |
| Diagnostics/inputs/outputs display | ● | ● |
| Load or save device configurations | ● | ● |
| Smart Meter Verification launch | ● | ● |
| Smart Meter Verification reports | ● | ● |
| Process variable trending | | ● |
| Offline configuration management | | ● |
| Device simulation | | ● |
| Data logging | | ● |
| Multidevice comparison tool | | ● |
| Guided process support tools | | ● |
| Modbus TCP support | | ● |
| Print Configuration | | ● |




ProLink® III Configuration and Service Software

Simulate a device or create an offline configuration

Connect to and navigate between multiple devices simultaneously

At a glance, you can quickly see your key process variables and diagnostics data – allowing you to better manage your system performance

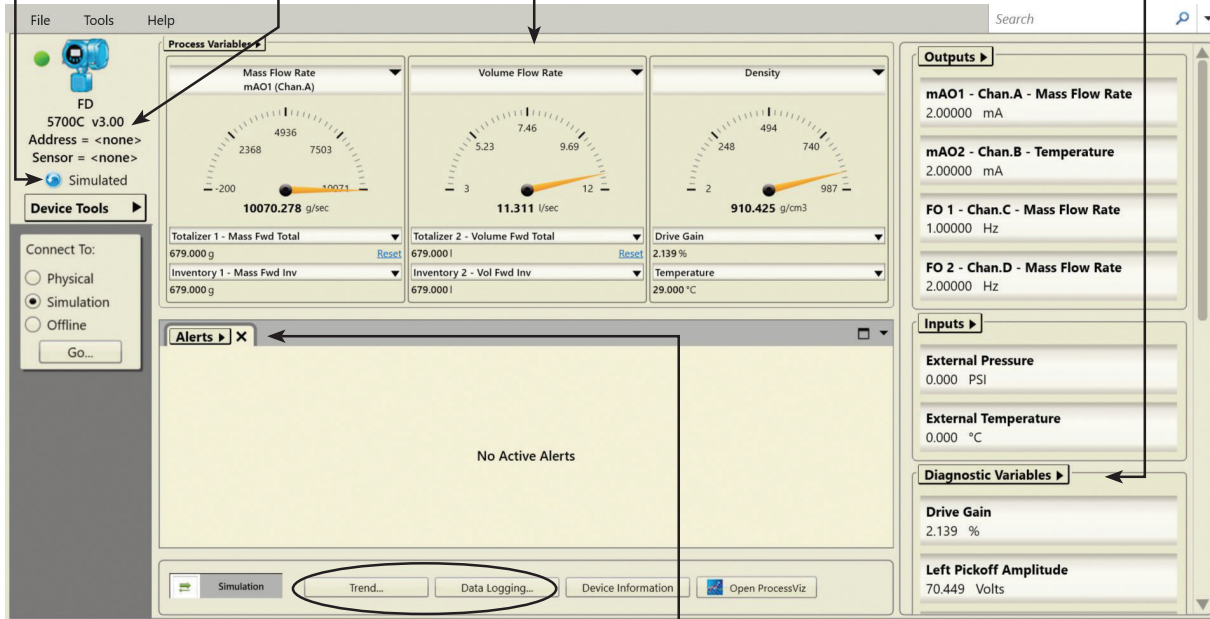

Monitor flow meter performance by charting process trends and logging system data

Easy access to active alerts, and receive immediate support in understanding how to respond to the issues

To learn more, visit us at:
www.Emerson.com/ProLink

Emerson Automation Solutions

7070 Winchester Circle
 Boulder, Colorado USA 80301
 T: +1 800-522-6277
 Mexico: +52 55 5809 5300
 Argentina: +54 11 4809 2700
 Brazil: +55 15 3413 8000
 Chile: +56 2 2928 48 00
 Peru: +51 15190130

Emerson Automation Solutions

Central Europe: +41 41 7686 111
 Eastern Europe: +41 41 7686 111
 Dubai: +971 4 811 8100
 Abu Dhabi: +971 2 697 2000
 Austria: +43 2236 607-0
 France: 0800 917 901
 Germany: +49 (0) 2173 3348 0
 Italy: 8008 77334
 The Netherlands: +31 318 495 555
 Belgium: +32 2 716 77 11
 Spain: 900 901 986
 U.K.: 0870 240 1978
 Russian/CIS: +7 495 995 9559

Emerson Automation Solutions

Australia: (61) 3 9721 0200
 China: (86) 21 2892 9000
 India: (91) 22 6662 0566
 Japan: (81) 3 5769 6803
 South Korea: (82) 31 8034 0000
 Singapore: (65) 6 363 7766

