

# NEER™ Cable Staples

NEC/CEC:  
Rated for Ordinary Locations

## SN: Cable Staples

### Applications

- To secure nonmetallic sheathed cable and type SE/U cable to wooden mounting structure.

### Standard Material

- Steel


Note:

- SN cable staples are furnished in plastic containers.



SN

### Illustrated Dimensions

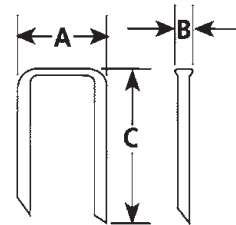

Trade Size (Inches)	Dimensions in Millimeters (Inches)			Carton	Standard Package	Catalog Number
	A	B	C			
<b>NMC 2-Cond. 12 and 14</b>						
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	100	10,000	SN-400
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	500	10,000	SN-405
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	-	15,000	SN-410
<b>NMC 3-Cond. 10-12 and 14 Wire</b>						
1-1/4 x 9/16	20.3 (0.8)	3.6 (0.14)	34.8 (1.37)	100	5,000	SN-1000
1-1/4 x 9/16	20.3 (0.8)	3.6 (0.14)	34.8 (1.37)	500	5,000	SN-1050
1-1/4 x 9/16	20.3 (0.8)	3.6 (0.14)	34.8 (1.37)	-	10,000	SN-1100
<b>SE/U 3-Cond. No. 6</b>						
1-3/8 x 13/16	33.0 (1.3)	6.6 (0.26)	33.5 (1.32)	100	5,000	SN-3000

# NEER™ Cable Staples

NEC/CEC:  
Rated for Ordinary Locations

## SN: Cable Staples

### Applications

- To secure nonmetallic sheathed cable and type SE/U cable to wooden mounting structure.

### Standard Material

- Steel


Note:

- SN cable staples are furnished in plastic containers.



SN

### Illustrated Dimensions

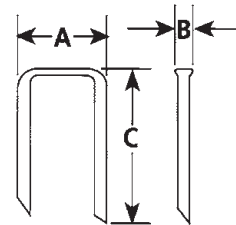

Trade Size (Inches)	Dimensions in Millimeters (Inches)			Carton	Standard Package	Catalog Number
	A	B	C			
<b>NMC 2-Cond. 12 and 14</b>						
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	100	10,000	SN-400
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	500	10,000	SN-405
1 X 1/2	18.5 (0.73)	3.3 (0.13)	28.4 (1.12)	-	15,000	SN-410
<b>NMC 3-Cond. 10-12 and 14 Wire</b>						
1-1/4 x 9/16	20.3 (0.80)	3.6 (0.14)	34.8 (1.37)	100	5,000	SN-1000
1-1/4 x 9/16	20.3 (0.80)	3.6 (0.14)	34.8 (1.37)	500	5,000	SN-1050
1-1/4 x 9/16	20.3 (0.80)	3.6 (0.14)	34.8 (1.37)	-	10,000	SN-1100
<b>SE/U 3-Cond. No. 6</b>						
1-3/8 x 13/16	33.0 (1.30)	6.6 (0.26)	33.5 (1.32)	100	5,000	SN-3000