

# EMT Straps

**CEC:**  
*Rated for Ordinary Locations*

## Features

- Snap type-double ribbed.

## Standard Materials


- Steel

## Standard Finishes

- Zinc plated

## CEC Certifications and Compliances


- CSA Standard: C22.2 No. 18
- CSA Certified: 9795

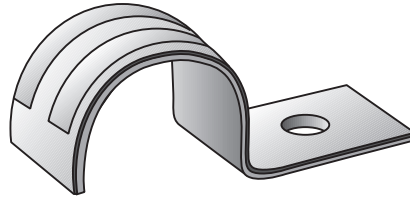

**Type 15**

# EMT Straps

**CEC:**  
Rated for Ordinary Locations

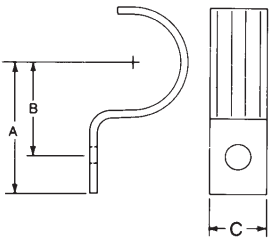	Trade Size (Inches)	Dimensions in Millimeters (Inches)			Bolt Size	Catalog Number
		A	B	C		
<b>One Hole</b>						
 <p><b>Type 15</b></p>	1/2	31.75 (1.25)	22.35 (0.88)	14.22 (0.56)	6.35 (0.25)	<b>15-50S</b>
	3/4	35.05 (1.38)	26.92 (1.06)	16.00 (0.63)	6.35 (0.25)	<b>15-75S</b>
	1	41.40 (1.63)	31.75 (1.25)	19.05 (0.75)	6.35 (0.25)	<b>15-100S</b>
	1-1/4	50.80 (2.00)	38.10 (1.50)	22.35 (0.88)	7.87 (0.31)	<b>15-125S</b>
	1-1/2	54.10 (2.13)	42.93 (1.69)	25.40 (1.00)	9.65 (0.38)	<b>15-150S</b>
	2	66.80 (2.63)	50.80 (2.00)	28.70 (1.13)	11.18 (0.44)	<b>15-200S</b>
	2-1/2	111.25 (4.38)	66.80 (2.63)	31.75 (1.25)	12.70 (0.50)	<b>14-250S</b>
	3	120.65 (4.75)	76.20 (3.00)	31.75 (1.25)	12.70 (0.50)	<b>14-300S</b>
	3-1/2	131.83 (5.19)	90.42 (3.56)	38.10 (1.50)	16.00 (0.63)	<b>14-350S</b>
	4	138.18 (5.44)	100.08 (3.94)	38.10 (1.50)	16.00 (0.63)	<b>14-400S</b>